


## Dies for system 1311 and 1300

Pressing dies for hydraulic pressing pliers V 1311 and battery pressing plier PVX 1300

### Info

NEW: two-stage DUAL crimping technique (first hexagonal pressing, then additional mandrel pressing)

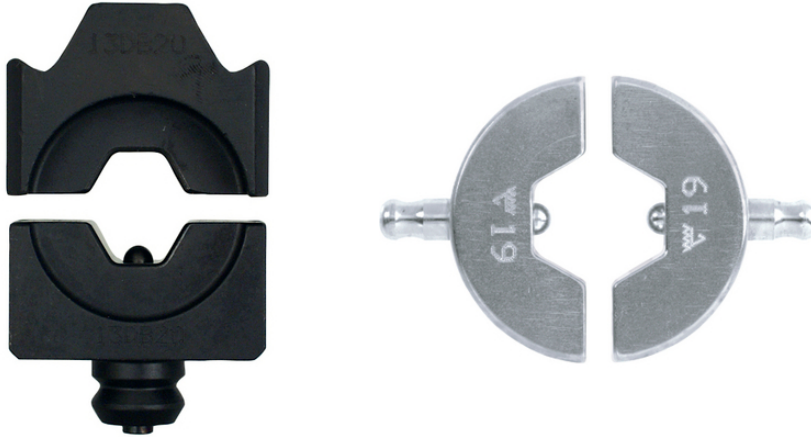

### Application range

Pressing dies for V 1311 and PVX 1300 for crimping cable lugs (KRT/KRF) and butt connectors (KST/KSF)

### Included

Pressing dies are delivered in pairs

No die holders are required for type "13DB" or "13B" crimping dies. Die holders must be ordered separately for type "B" crimping dies.

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001282

ETIM 5.0 Class-Description: Insert for crimp tool cable lugs, cable end sleeves, screen connection

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001282

ETIM 6.0 Class-Description: Insert for crimp tool cable lugs, cable end sleeves, screen connection

### Note

Component composition: First specify the pressing dies. Note that die holders are not needed for all pressing dies (depending on the cross section of the tube cable lugs to be pressed)

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

**Dies for system 1311 and 1300**

| Article number          | Article designation | For KRT/KST mm <sup>2</sup> | For KRF/KSF mm <sup>2</sup> | PU |
|-------------------------|---------------------|-----------------------------|-----------------------------|----|
| Pressing dies hexagonal |                     |                             |                             |    |
| 61795950                | B7                  | 10                          | -                           | 1  |
| 61795951                | B8                  | -                           | 10                          | 1  |
| 61795960                | B8,5                | 16                          | -                           | 1  |
| 61795970                | B9                  | -                           | 16                          | 1  |
| 61795971                | B10                 | 25                          | -                           | 1  |
| 61795972                | B11                 | -                           | 25                          | 1  |
| 61795980                | B12                 | 35                          | -                           | 1  |
| 61795981                | B13                 | -                           | 35                          | 1  |
| 61795990                | B14                 | 50                          | -                           | 1  |
| 61795991                | B14,5               | -                           | 50                          | 1  |
| 61796000                | B16                 | 70                          | -                           | 1  |
| 61796001                | B17                 | -                           | 70                          | 1  |
| 61796010                | B18                 | 95                          | -                           | 1  |
| 61796020                | B19                 | 120                         | -                           | 1  |
| 61796021                | B20                 | -                           | 95                          | 1  |
| 61796030                | B22                 | 150                         | 120                         | 1  |
| 61796031                | B24                 | 185                         | -                           | 1  |
| 61796032                | B25                 | -                           | 150                         | 1  |
| 61796043                | 13B26               | 240                         | -                           | 1  |
| 61796044                | 13B30               | 300                         | 240                         | 1  |
| 61796045                | 13B32               | 400                         | 300                         | 1  |
| 61796046                | 13B38               | -                           | 400                         | 1  |