


## SKINDICHT® A-PG/M

SKINDICHT® A-PG/M Adapter from PG outer thread to M inner thread

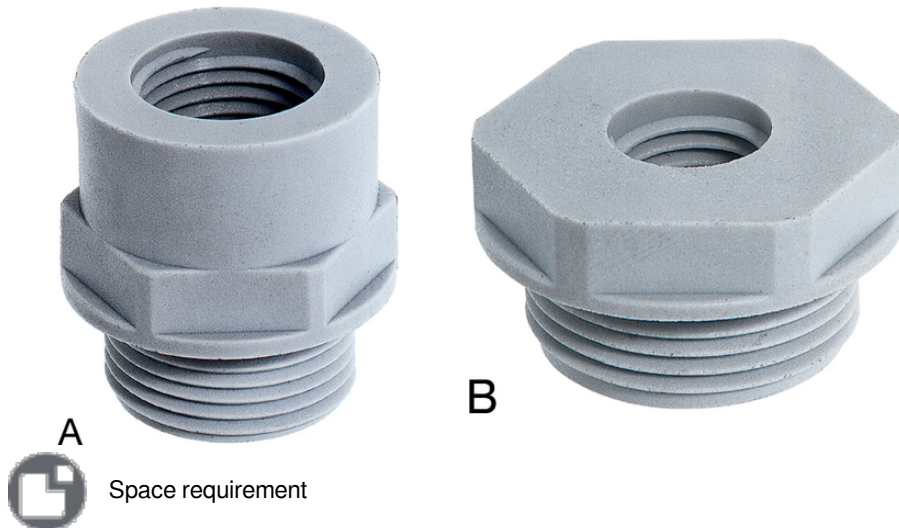

### Benefits

Allows easy transition from a PG external thread to a metric internal thread.

### Application range

Housings  
Industrial connectors  
Machines

### Product Make-up

PG connection thread

### Product Make-up

Form A = high  
Form B = flat

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000441

ETIM 5.0 Class-Description: Cable screw gland

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000441

ETIM 6.0 Class-Description: Cable screw gland

Colour delivered:

Light grey (RAL 7035)

Material:

Polyamide, glass fibre-reinforced

Temperature range:

-40°C to +100°C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.

Last Update (24.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## SKINDICHT® A-PG/M

| Article number    | Form | Thread, male PG | Thread, female M2 | SW wrench size mm | Pieces / PU |
|-------------------|------|-----------------|-------------------|-------------------|-------------|
| SKINDICHT® A-PG/M |      |                 |                   |                   |             |
| 52100320          | A    | PG 7            | 12 x 1.5          | 16                | 25          |
| 52100321          | A    | PG 7            | 16 x 1.5          | 20                | 25          |
| 52100322          | A    | PG 9            | 12 x 1.5          | 20                | 25          |
| 52100323          | A    | PG 9            | 16 x 1.5          | 20                | 25          |
| 52100324          | A    | PG 9            | 20 x 1.5          | 24                | 25          |
| 52100325          | A    | PG 11           | 16 x 1.5          | 22                | 25          |
| 52100326          | A    | PG 11           | 20 x 1.5          | 24                | 25          |
| 52100327          | A    | PG 11           | 25 x 1.5          | 29                | 25          |
| 52100328          | A    | PG 13.5         | 16 x 1.5          | 24                | 25          |
| 52100329          | A    | PG 13.5         | 20 x 1.5          | 24                | 25          |
| 52100330          | A    | PG 13.5         | 25 x 1.5          | 29                | 25          |
| 52100331          | A    | PG 16           | 20 x 1.5          | 27                | 25          |
| 52100332          | A    | PG 16           | 25 x 1.5          | 29                | 25          |
| 52100333          | A    | PG 16           | 32 x 1.5          | 36                | 25          |
| 52100334          | A    | PG 21           | 25 x 1.5          | 33                | 10          |
| 52100335          | A    | PG 21           | 32 x 1.5          | 36                | 10          |
| 52100336          | A    | PG 21           | 40 x 1.5          | 46                | 10          |
| 52100337          | B    | PG 29           | 32 x 1.5          | 42                | 10          |
| 52100338          | A    | PG 29           | 40 x 1.5          | 46                | 10          |
| 52100339          | A    | PG 29           | 50 x 1.5          | 55                | 10          |
| 52100340          | B    | PG 36           | 40 x 1.5          | 53                | 10          |
| 52100341          | A    | PG 36           | 50 x 1.5          | 55                | 10          |
| 52100342          | A    | PG 36           | 63 x 1.5          | 68                | 10          |
| 52100343          | B    | PG 42           | 40 x 1.5          | 60                | 5           |
| 52100344          | A    | PG 42           | 50 x 1.5          | 60                | 5           |
| 52100345          | A    | PG 42           | 63 x 1.5          | 68                | 5           |
| 52100346          | B    | PG 48           | 50 x 1.5          | 65                | 5           |
| 52100347          | A    | PG 48           | 63 x 1.5          | 68                | 5           |