


EPIC® M-D 1.0 D-Sub stamped contacts-on-reel

For inserts and modules of the EPIC® rectangular connectors

Info

Gold plated contacts in 2 quality levels
for automated production with crimping machine
Two crimp areas with wire and insulation crimp

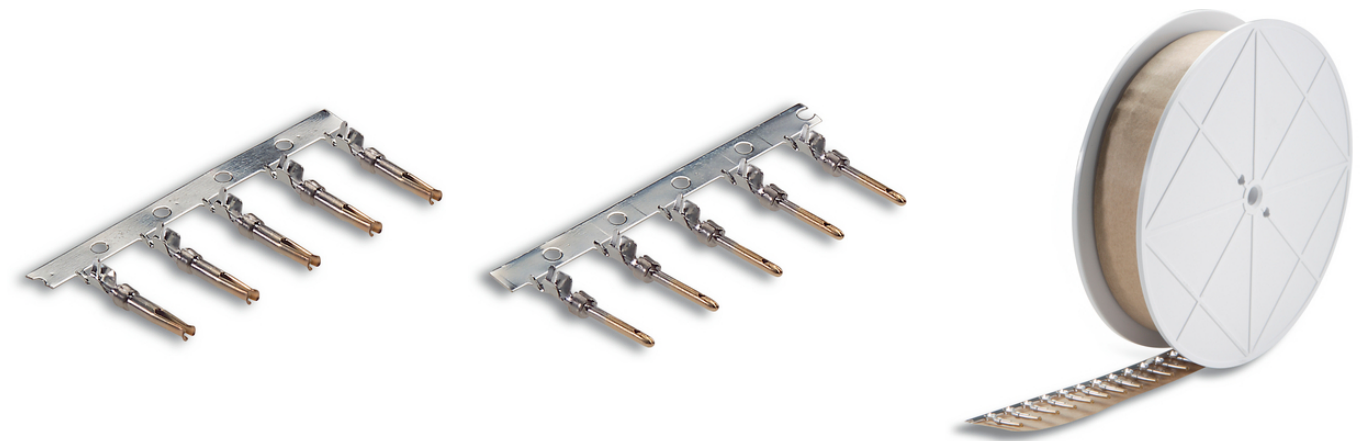

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000796

ETIM 5.0 Class-Description: Contact for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000796

ETIM 6.0 Class-Description: Contact for industrial connectors

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

EPIC® M-D 1.0 D-Sub stamped contacts-on-reel

Article number	Article description	Contact type	Conductor cross-section (mm²)	Surface	Stripping length (mm)	Note	Pieces / PU
Contacts							
44429011	EPIC® D-SUB SCBG AU G2 0,08-0,22 (500)	male	0.08 - 0.22	Au (0.8 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1
44429007	EPIC® D-SUB BCBG AU G2 0,08-0,22 (500)	female	0.08 - 0.22	Au (0.8 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1
44429013	EPIC® D-SUB SCBG AU G3 0,08-0,22 (500)	male	0.08 - 0.22	Au (0.1 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1
44429009	EPIC® D-SUB BCBG AU G3 0,08-0,22 (500)	female	0.08 - 0.22	Au (0.1 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1
44429012	EPIC® D-SUB SCBG AU G2 0,22-0,56 (500)	male	0.22 - 0.56	Au (0.8 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1
44429008	EPIC® D-SUB BCBG AU G2 0,22-0,56 (500)	female	0.22 - 0.56	Au (0.8 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1
44429014	EPIC® D-SUB SCBG AU G3 0,22-0,56 (500)	male	0.22 - 0.56	Au (0.1 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1
44429010	EPIC® D-SUB BCBG AU G3 0,22-0,56 (500)	female	0.22 - 0.56	Au (0.1 µm)	2.5 + 0.5	1 reel (PU) = 500 contacts	1

EPIC® M-D 1.0 D-Sub stamped contacts-on-reel