


## EPIC® H-B 32 SGRL

Housing design H-B for 2 inserts.

This connector housing with 2 double levers and 2 cable entries can be used in investment construction and the plastics industry.

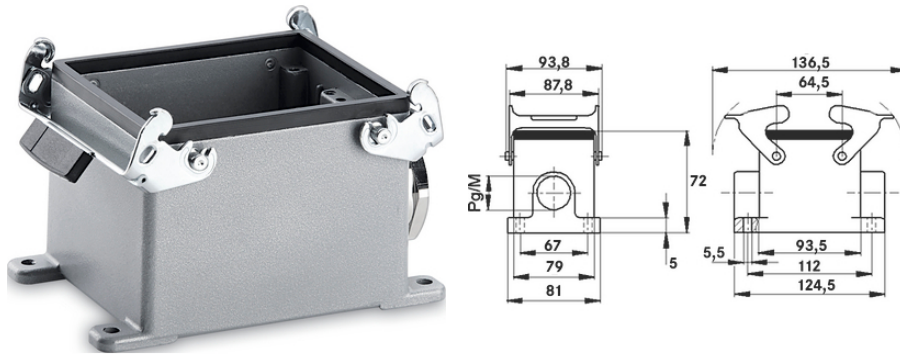

### Benefits

Two inserts in one housing. With two levers for high safety

M40 housing extension on M50 with SKINTOP 53112083 possible (clamping range 27 - 35 mm)

### Application range

Plant engineering

Control engineering

Plastics industry

### Product features

Surface-mount base

Dual levers

2 cable entries

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel

Sealing: NBR

Protection rating:

IP 65 (latched)

Temperature range:

-40°C to +100°C, short-term up to +125°C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Last Update (12.01.2024)

©2024 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## EPIC® H-B 32 SGRL

Prices are net prices without VAT and surcharges. Sale to business customers only.

## EPIC® H-B 32 SGRL

Article number	Article description	M	PG	Pieces / PU
H-B housing: surface-mount base (2 cable entries, double lever)				
10138000	H-B 32 SGRL 29	-	29	5
19138000	H-B 32 SGRL M32	32	-	5
19145400	H-B 32 SGRL M40	40	-	5