


## EPIC® H-B 48 AD-LB

Housing design H-B for 2 inserts.

The robust, large housing consists of the pivots for a single lever, a seal and a thermoplastic cap and is suitable for investment construction applications.

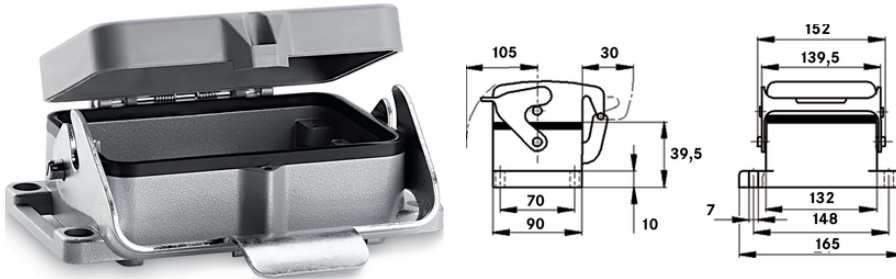

### Benefits

The large, robust housing for two inserts in one connector. Power and data in a single connector

### Application range

Plant engineering  
Plastics industry

### Product features

H-A case: Wall base  
Single lever  
Plastic cover  
Included: flat gasket

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel

Sealing: NBR

Protection rating:

IP 65 (latched)

Temperature range:

-40°C to +100°C, short-term up to +125°C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.

**EPIC® H-B 48 AD-LB**

Article number	Article description	
H-B housing: panel-mount base (cover, single lever)		M
10152000	H-B 48 AD-LB	AG

Last Update (23.05.2019)

©2019 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.  
PN 0456 / 02\_03.16