


## EPIC® H-B 48 SDR-LB

Housing design H-B for 2 inserts.

The large housing for the placement of two inserts consists of a single lever, a cable entry and a thermoplastic cap.

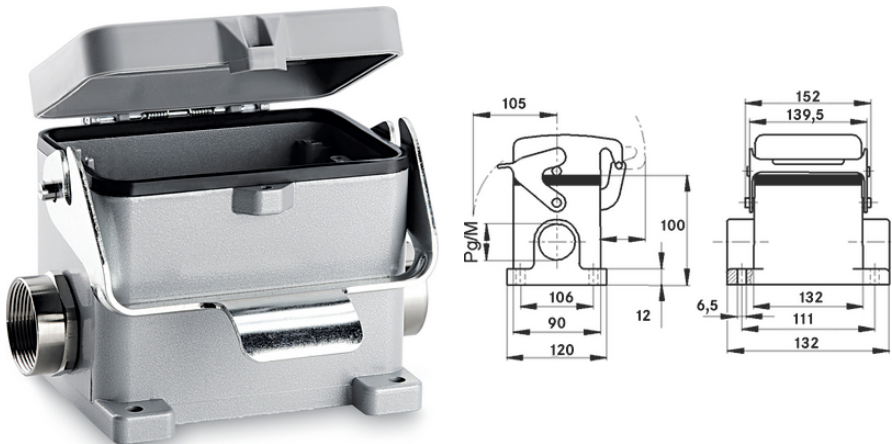

### Benefits

The large, robust housing for two inserts in one connector. Power and data in a single connector  
M40 housing extension on M50 with SKINTOP 53112083 possible (clamping range 27 - 35 mm)

### Application range

Plant engineering  
Plastics industry

### Product features

Surface-mount base  
Single lever  
1 cable entry  
Plastic cover

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel

Sealing: NBR

Protection rating:

IP 65 (latched)

Temperature range:

-40°C to +100°C, short-term up to +125°C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Last Update (23.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## EPIC® H-B 48 SDR-LB

Prices are net prices without VAT and surcharges. Sale to business customers only.

**EPIC® H-B 48 SDR-LB**

| Article number                                                       | Article description | M  | PG | Pieces / PU |
|----------------------------------------------------------------------|---------------------|----|----|-------------|
| H-B housing: surface-mount base (cover, 1 cable entry, single lever) |                     |    |    |             |
| 10167000                                                             | H-B 48 SDR 29       | -  | 29 | 1           |
| 10167100                                                             | H-B 48 SDR 36       | -  | 36 | 1           |
| 19167000                                                             | H-B 48 SDR M32      | 32 | -  | 1           |
| 19167100                                                             | H-B 48 SDR M40      | 40 | -  | 1           |