


## EPIC® H-Q Surface mount base plastic

EPIC® H-Q Surface mount base plastic housing for H-Q rectangular connector series

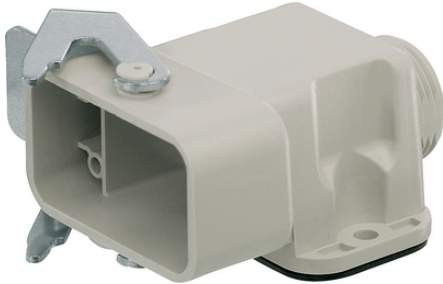

Corrosion-resistant



Low weight



Optimum strain relief

### Benefits

Housing in plastic or metal version. For power supply in the smallest possible space neck for cable gland integrated, use with special H-Q cable glands with metal housing EMC cable gland as an option

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Material:

Housing: thermoplastic, grey

Lever: metal

Protection rating:

IP 66

Temperature range:

-40 °C to +125 °C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.

## EPIC® H-Q Surface mount base plastic

Article number	Article description	M	Pieces / PU
H-Q housings – surface-mount bases (1 cable entry)			
44420532	H-Q SGR V16P	V16P	1