


## FLEXIMARK® Cablemarking FCC

FLEXIMARK® CABLE MARKER FCC- customized cable marking with a character holder made of plastic to attach to cables with cable ties

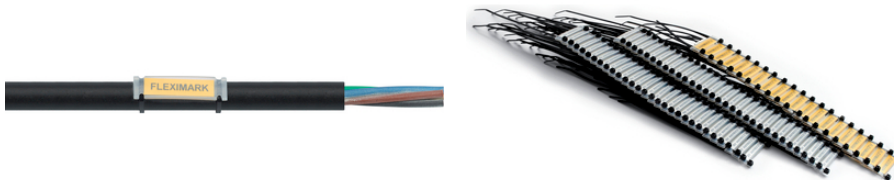

Suitable for outdoor use



Good chemical resistance



Assembly time



Acid-resistant



UV-resistant

### Benefits

No time-consuming preparation and installation

Resistant to chemicals, UV-light, moisture and oils (diesel oil, basic cleaning agent, sea water, ethanol,...)

### Application range

For cable marking

### Note

Markers will be delivered with the desired text (printing service is included in the price)

One or two-line printing possible

Text length is depending on the size of the label and the readability- in general there is no word limitation

Ordering process: Customer-specific data will be emailed as an Excel file to the responsible Lapp employee when the order is made

Column A: Row 1 content

Column B: Row 2 content

Column B or C: Number of markers with corresponding text

Print jobs template: [www.lappkabel.com/service/downloadcenter/markingsystem/fleximark-customized-markings.html](http://www.lappkabel.com/service/downloadcenter/markingsystem/fleximark-customized-markings.html)

### Included

Marking consists of FLEXIMARK® Character holder PTEF, printed PVC label (not halogen-free) or FLEXIMARK® Flexilabel LFL

Last Update (24.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## FLEXIMARK® Cablemarking FCC

(halogen-free) and two standard cable ties in PA 6.6 (black)  
Markers (including cable ties) are pre-assembled prior to delivery  
1 PU= 1 marker, there is no minimum purchase quantity

### Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC001288 ETIM 5.0 Class-Description: Labelling material
Classification ETIM 6:	ETIM 6.0 Class-ID: EC001288 ETIM 6.0 Class-Description: Labelling material
Note:	Standard cable tie: black (142 x 2.4 mm)
Dimensions:	Length text: 35 mm Length plate: 50 mm
Colour delivered:	Standard colour: black lettering against yellow or white background Also available in green, blue and red
Material:	Character holder: halogen-free PE Labels: Not halogen-free PVC or halogenfree polyester (LFL version)
Temperature range:	-30 °C to +70 °C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.  
FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

**FLEXIMARK® Cablemarking FCC**

Article number	Article designation	Colour	Height (mm)	Markers / PU
With yellow PVC markers (not halogenfree)				
83251300	FLEXIMARK® Cable marker FCC 6 YE	yellow	6.0	1
83251320	FLEXIMARK® Cable marker FCC 9,5 YE	yellow	9.5	1
83251350	FLEXIMARK® Cable marker FCC 19 YE	yellow	19.0	1
With yellow LFL labels made of polyester (halogenfree)				
83274670	FLEXIMARK® Cable marker LFL 9,5-35 YE FCC	yellow	9.5	1
With white PVC markers (not halogenfree)				
83251301	FLEXIMARK® Cable marker FCC 6 WH	white	6.0	1
83251321	FLEXIMARK® Cable marker FCC 9,5 WH	white	9.5	1
83251351	FLEXIMARK® Cable marker FCC 19 WH	white	19.0	1

Last Update (24.04.2024)

©2024 Lapp Group - Technical changes reserved

 Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03\_16