


FLEXIMARK® Shrink mark FCC

FLEXIMARK® Shrink mark FCC - customized printed shrink hoses, particularly for the rail industry

Info

Shrink mark FK 12.7 RD 5-7 included in FLEXIMARK® sample bag (article no. M3251010)

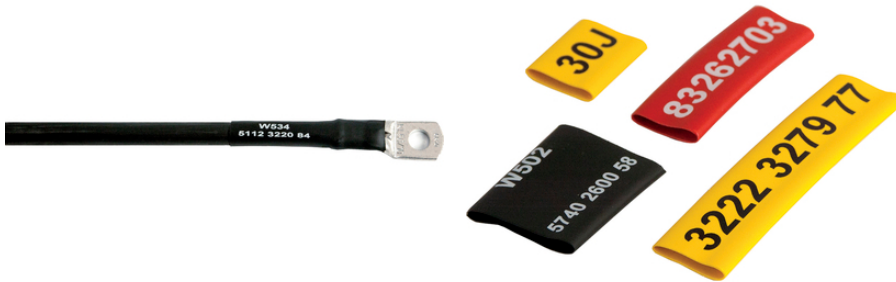

Mechanical and plant engineering



Good chemical resistance



Flame-retardant



Halogen-free



Assembly time

Benefits

Personalised printing of the shrinking tube segments according to customer specifications
Protection of the cable insulation

Application range

For cable marking
For applications where space is tight
E.g. for applications in the railway or wind industry

Norm references / Approvals

Flame retardant according to
ASTM D635-HB

Note

Markers will be delivered with the desired text (printing service is included in the price)
One or two-line printing possible
Please specify the desired text colour, mode of delivery (perforation or cut,lengths) and other requirements (e.g. textalignments)

Last Update (24.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

FLEXIMARK® Shrink mark FCC

with your order

Ordering process: Customer-specific data will be emailed as an Excel file to the responsible Lapp employee when the order is made

Column A: Row 1 content

Column B: Row 2 content

Column B or C: Number of markers with corresponding text

Print jobs template: www.lappkabel.com/service/downloadcenter/markingsystem/fleximark-customized-markings.html

Included

1 PU= 1 marker, there is no minimum purchase quantity

Delivery either in cutted pieces or in one piece (already perforated)

Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC001288 ETIM 5.0 Class-Description: Labelling material
Classification ETIM 6:	ETIM 6.0 Class-ID: EC001288 ETIM 6.0 Class-Description: Labelling material
Colour delivered:	Black Also available in blue, red, yellow, white
Material:	Polyolefin
Shrinking ratio:	2:1
Temperature range:	-55°C to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

FLEXIMARK® Shrink mark FCC

Article number	Article designation	Colour	Ø before shrinking (mm)	Ø after shrinking (mm)	Number of characters	Markers / PU
83280029	FLEXIMARK® Shrink mark FCC-FK 3,2 BK	black	3.2	1.6	1-7	1
83280030	FLEXIMARK® Shrink mark FCC-FK 3,2 BK	black	3.2	1.6	8-12	1
83280031	FLEXIMARK® Shrink mark FCC-FK 3,2 BK	black	3.2	1.6	13-17	1
83280032	FLEXIMARK® Shrink mark FCC-FK 4,8 BK	black	4.8	2.4	1-7	1
83280033	FLEXIMARK® Shrink mark FCC-FK 4,8 BK	black	4.8	2.4	8-12	1
83280034	FLEXIMARK® Shrink mark FCC-FK 4,8 BK	black	4.8	2.4	13-17	1
83280035	FLEXIMARK® Shrink mark FCC-FK 6,4 BK	black	6.4	3.2	1-7	1
83280036	FLEXIMARK® Shrink mark FCC-FK 6,4 BK	black	6.4	3.2	8-12	1
83280037	FLEXIMARK® Shrink mark FCC-FK 6,4 BK	black	6.4	3.2	13-17	1
83280038	FLEXIMARK® Shrink mark FCC-FK 9,5 BK	black	9.5	4.75	1-7	1
83280039	FLEXIMARK® Shrink mark FCC-FK 9,5 BK	black	9.5	4.75	8-12	1
83280040	FLEXIMARK® Shrink mark FCC-FK 9,5 BK	black	9.5	4.75	13-17	1
83280041	FLEXIMARK® Shrink mark FCC-FK 12,7 BK	black	12.7	6.35	1-7	1
83280042	FLEXIMARK® Shrink mark FCC-FK 12,7 BK	black	12.7	6.35	8-12	1
83280043	FLEXIMARK® Shrink mark FCC-FK 12,7 BK	black	12.7	6.35	13-17	1
83280044	FLEXIMARK® Shrink mark FCC-FK 19,1 BK	black	19.1	9.55	1-7	1
83280045	FLEXIMARK® Shrink mark FCC-FK 19,1 BK	black	19.1	9.55	8-12	1
83280046	FLEXIMARK® Shrink mark FCC-FK 19,1 BK	black	19.1	9.55	13-17	1

Last Update (24.04.2024)

©2024 Lapp Group - Technical changes reserved

 Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16