


FLEXIMARK® Flexilabel LFL

FLEXIMARK® Flexilabel LFL are blank label sheets for marking cables with character holders. Text can be printed on the labels with our marking software and commercial laser printers.

Info

LFL 9.5-35 included in FLEXIMARK® sample bag (article no. M3251010)

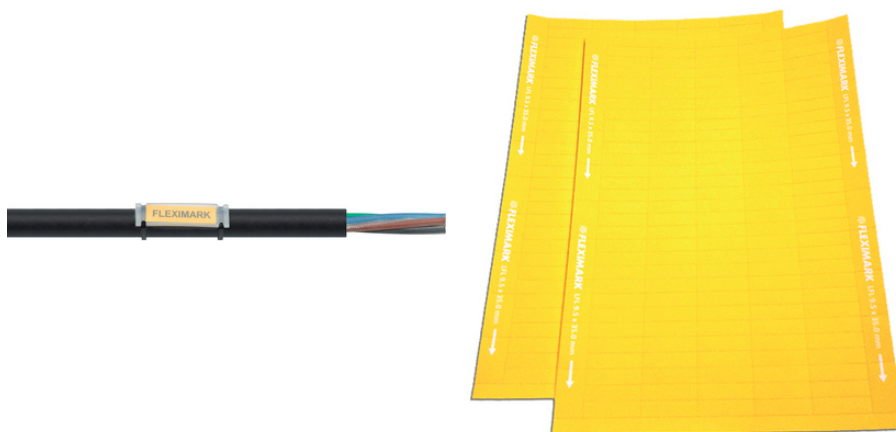

Good chemical resistance



Halogen-free



UV-resistant

Benefits

Resistant to chemicals, UV-light, moisture and oils (diesel oil, basic cleaning agent, sea water, ethanol,...)

Printable on both sides

Application range

For cable marking

Suitable labels for PTE, PTEF and CAB character holders (see chapter "Character holders and accessories")

Note

Can be printed with the FLEXIMARK® Software and a commercial laser printer

Insert sheet in manual paper feed compartment

Optimum printing results from laser printers are achieved with straight sheet feed-in

Included

Perforated DIN A4 sheets

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001288

ETIM 5.0 Class-Description: Labelling material

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001288

ETIM 6.0 Class-Description: Labelling material

Last Update (31.12.2023)

©2023 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

FLEXIMARK® Flexilabel LFL

Colour delivered:	Yellow/White (can be printed on both sides)
Material:	Halogen-free polyester Thickness: 0.175 mm
Temperature range:	-40°C to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

FLEXIMARK® Flexilabel LFL

Article number	Article designation	Colour	Width x length (mm)	Markers / PU	PU
83254620	FLEXIMARK® Label LFL 6-35 YEWH	yellow/white	6.0 x 35.0	2350	1
83254650	FLEXIMARK® Label LFL 9.5-17.5 YEWH	yellow/white	9.5 x 17.5	3190	1
83254660	FLEXIMARK® Label LFL 9.5-28 YEWH	yellow/white	9.5 x 28.0	2030	1
83254670	FLEXIMARK® Label LFL 9.5-35 YEWH	yellow/white	9.5 x 35.0	1450	1
83254701	FLEXIMARK® Label LFL 9.9-66 YEWH	yellow/white	9.9 x 66.0	840	1
83254690	FLEXIMARK® Label LFL 9.5-196 YEWH	yellow/white	9.5 x 196.0	290	1
83254710	FLEXIMARK® Label LFL 12-38 YEWH	yellow/white	12.0 x 38.0	1150	1
83254714	FLEXIMARK® Label LFL 15-45 YEWH	yellow/white	15.0 x 45.0	720	1
83254718	FLEXIMARK® Label LFL 19-50 YEWH	yellow/white	19.0 x 50.0	560	1
83254719	FLEXIMARK® Label LFL 19-100 YEWH	yellow/white	19.0 x 100.0	280	1

Last Update (31.12.2023)

©2023 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16