


## FLEXIMARK® Shrink mark

FLEXIMARK® Flat Heat shrinkable tubing for cable marking can be easily printed with our software and a thermal transfer printer.

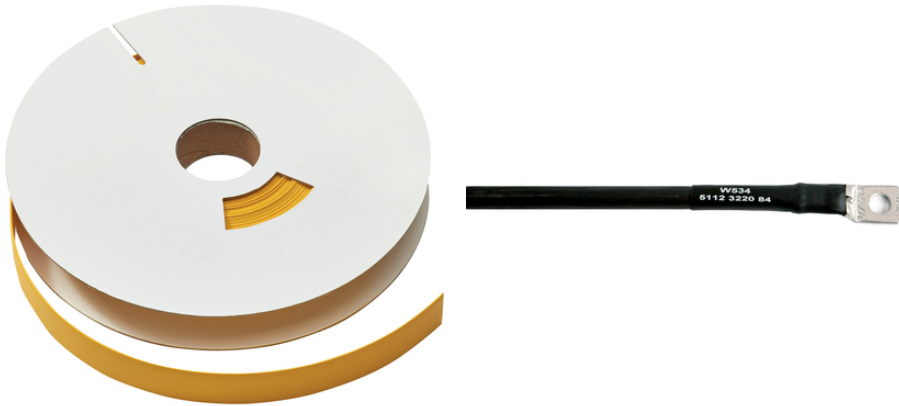

Wind Energy



Good chemical resistance



Flame-retardant

### Benefits

Flat shrink tube that can be cut individually to the required length

### Application range

For cable marking  
For applications where space is tight  
Protection of the cable insulation  
Especially suitable for repair purposes

### Norm references / Approvals

UL 224 certified

### Note

Can be printed with the FLEXIMARK® Software and the FLEXIMARK® Thermal transfer printer SQUIX or EOS5

Recommended ribbon:

Text colour black: FTI-X 60-300 BK (article no. 83260206),

Text colour white: FTI-X 55-300 WH (article no. 83260260)

Use the EOS5 printer with additional cutter for cutting, use the SQUIX printer with additional perforation cutter for perforating the shrink tubes

With customized print: see product FLEXIMARK® Shrink tube FCC

### Included

Delivered as a roll of labels

## FLEXIMARK® Shrink mark

### Technical Data

|                        |   |
|------------------------|---|
| Classification ETIM 5: | ETIM 5.0 Class-ID: EC001288<br>ETIM 5.0 Class-Description: Heat-shrink tubing |
| Classification ETIM 6: | ETIM 6.0 Class-Description: Shrink tubing                                     |
| Colour delivered:      | Black, yellow and white   |
| Material:              | Polyolefin<br>Shrinking ratio: 3:1  |
| Temperature range:     | -55°C to +135°C   |

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

**FLEXIMARK® Shrink mark**

| Article number | Article designation                  | Colour | Shrinkage range (mm) | PU (m) | PU |
|----------------|--------------------------------------|--------|----------------------|--------|----|
| 83251670       | FLEXIMARK® Shrinking tube<br>3/1 BK  | black  | 1.0 - 3.0            | 30     | 1  |
| 83251671       | FLEXIMARK® Shrinking tube<br>6/2 BK  | black  | 2.0 - 6.0            | 25     | 1  |
| 83251672       | FLEXIMARK® Shrinking tube<br>9/3 BK  | black  | 3.0 - 9.0            | 20     | 1  |
| 83251673       | FLEXIMARK® Shrinking tube<br>12/4 BK | black  | 4.0 - 12.0           | 20     | 1  |
| 83251674       | FLEXIMARK® Shrinking tube<br>18/6 BK | black  | 6.0 - 18.0           | 20     | 1  |
| 83251680       | FLEXIMARK® Shrinking tube<br>3/1 YE  | yellow | 1.0 - 3.0            | 30     | 1  |
| 83251681       | FLEXIMARK® Shrinking tube<br>6/2 YE  | yellow | 2.0 - 6.0            | 25     | 1  |
| 83251682       | FLEXIMARK® Shrinking tube<br>9/3 YE  | yellow | 3.0 - 9.0            | 20     | 1  |
| 83251683       | FLEXIMARK® Shrinking tube<br>12/4 YE | yellow | 4.0 - 12.0           | 20     | 1  |
| 83251684       | FLEXIMARK® Shrinking tube<br>18/6 YE | yellow | 6.0 - 18.0           | 20     | 1  |
| 83251690       | FLEXIMARK® Shrinking tube<br>3/1 WH  | white  | 1.0 - 3.0            | 30     | 1  |
| 83251691       | FLEXIMARK® Shrinking tube<br>6/2 WH  | white  | 2.0 - 6.0            | 25     | 1  |
| 83251692       | FLEXIMARK® Shrinking tube<br>9/3 WH  | white  | 3.0 - 9.0            | 20     | 1  |
| 83251693       | FLEXIMARK® Shrinking tube<br>12/4 WH | white  | 4.0 - 12.0           | 20     | 1  |
| 83251694       | FLEXIMARK® Shrinking tube<br>18/6 WH | white  | 6.0 - 18.0           | 20     | 1  |

Last Update (12.07.2020)

©2020 Lapp Group - Technical changes reserved

 Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03\_16