


## SILVYN® LTP-C

SILVYN® LTP coupler - nickel-plated brass conduit coupler

### Info

Connection of two conduits

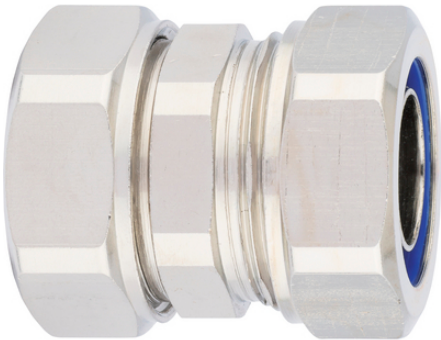

Assembly time



Space requirement



Robust



Reliability

### Benefits

Optional extension of SILVYN® LTP

Fast assembly

High tensile strength

### Application range

In combination with protective conduit:

SILVYN® LTP

Conduit coupler for extension

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001180

ETIM 5.0 Class-Description: Screw connection for protective metallic hose

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001180

ETIM 6.0 Class-Description: Screw connection for protective

Last Update (31.05.2023)

©2023 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

**SILVYN® LTP-C**

	metallic hose
Certifications:	IEC EN 61386-23
Material:	Nickel-plated brass
Protection rating:	IP66 IP67 IP68 (5 bar) IP69
Temperature range:	-50°C to +135°C

**Note**

Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.



## SILVYN® LTP-C

Article number	Nominal size	Suitable for SILVYN® LTP	Pieces / PU
SILVYN® LTP-C			
55510310	16	16	2
55510311	20	20	2
55510312	25	25	2
55510313	32	32	2

Last Update (31.05.2023)

©2023 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03\_16