


SILVYN® LTP-C

SILVYN® LTP coupler - nickel-plated brass conduit coupler

Info

Connection of two conduits

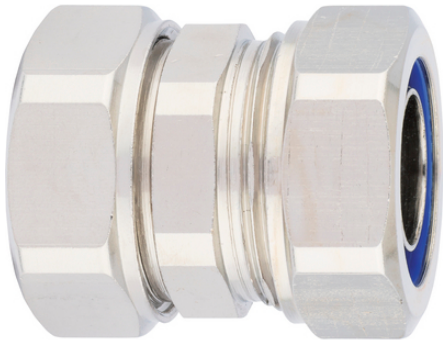

Assembly time



Space requirement



Robust



Reliability

Benefits

Optional extension of SILVYN® LTP

Fast assembly

High tensile strength

Application range

In combination with protective conduit:

SILVYN® LTP

Conduit coupler for extension

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001180

ETIM 5.0 Class-Description: Screw connection for protective metallic hose

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001180

ETIM 6.0 Class-Description: Screw connection for protective

Last Update (11.05.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SILVYN® LTP-C

	metallic hose
Certifications:	IEC EN 61386-23
Material:	Nickel-plated brass
Protection rating:	IP66 IP67 IP68 (5 bar) IP69
Temperature range:	-50°C to +135°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.



SILVYN® LTP-C

Article number	Nominal size	Suitable for SILVYN® LTP	Pieces / PU
SILVYN® LTP-C			
55510310	16	16	2
55510311	20	20	2
55510312	25	25	2
55510313	32	32	2

Last Update (1.05.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16