


SILVYN® LCC-C

SILVYN® LCC coupler - nickel-plated brass conduit coupler

Info

Connection of two conduits

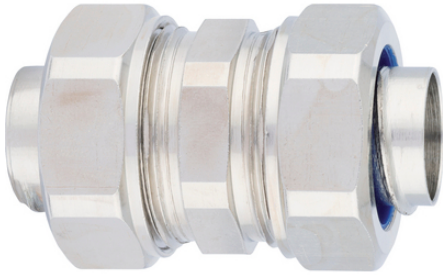

Assembly time



Space requirement



Robust



Reliability

Benefits

Optional extension of SILVYN® LCC-2 / LCCH-2

Fast assembly

High tensile strength

Application range

In combination with protective conduit:

SILVYN® LCC-2 / LCCH-2

Conduit coupler for extension

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001180

ETIM 5.0 Class-Description: Screw connection for protective metallic hose

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001180

ETIM 6.0 Class-Description: Screw connection for protective

Last Update (24.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SILVYN® LCC-C

	metallic hose
Certifications:	IEC EN 61386-23
Material:	Nickel-plated brass
Protection rating:	IP 65
Temperature range:	-50 °C to +135 °C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.



SILVYN® LCC-C

Article number	Nominal size	Suitable for SILVYN® LCC-2/LCCH-2	Pieces / PU
55503476	16	16	2
55503477	20	20	2
55503478	25	25	2
55503479	32	32	2

Last Update (24.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16