


SILVYN® LGEP

SILVYN® LGEP is a nickel-plated brass conduit insert

Info

Ensuring cables do not get damaged

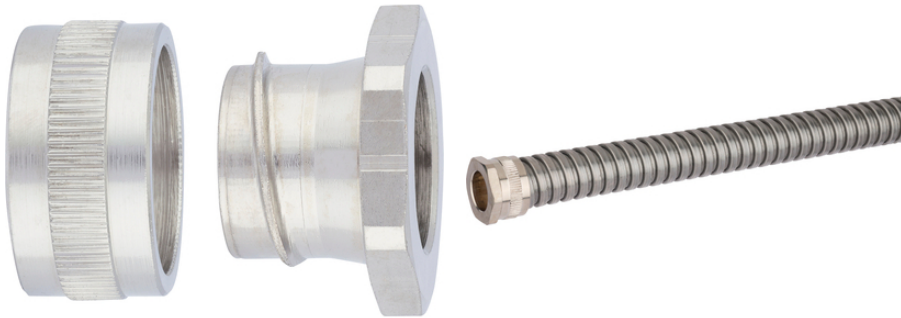

Benefits

Cable damage can be prevented
High tensile strength
Space-saving

Application range

In combination with protective conduit:
SILVYN® SSU / SSUE
Conduit end cover
If no conduit fitting is used
Applications with high mechanical stress

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001180

ETIM 5.0 Class-Description: Screw connection for protective metallic hose

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001180

ETIM 6.0 Class-Description: Screw connection for protective metallic hose

Certifications:

IEC EN 61386-23

Material:

Nickel-plated brass

Protection rating:

IP 40

Temperature range:

-50 °C to +300 °C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

SILVYN® LGEP

| Article number | Nominal size | Suitable for SILVYN® SSU / SSUE | Pieces / PU |
|----------------|--------------|---------------------------------|-------------|
| SILVYN® LGEP | | | |
| 55503179 | 10 | 10 | 10 |
| 55503180 | 12 | 13 | 10 |
| 55503181 | 16 | 16 | 10 |
| 55503182 | 20 | 20 | 10 |
| 55503183 | 25 | 25 | 10 |
| 55503184 | 32 | 32 | 10 |
| 55503185 | 40 | 40 | 4 |
| 55503186 | 50 | 50 | 4 |
| 55503187 | 63 | 63 | 1 |
| 55503188 | 75 | 75 | 1 |

Last Update (25.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16